



High Torque Timing Belts (P2M, P3M, P5M, P8M)

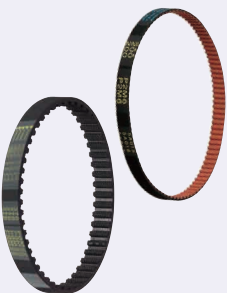

PTBN

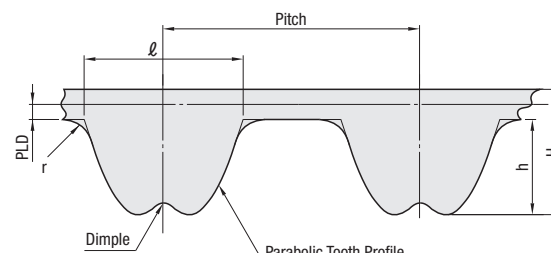

Pitch: ℓ

PLD: r

H: H

h: h

Material: PTBN

Operating Temp.: -15~80°C

Type	Main Body	Core Wire
PTBN	Chloroprene Rubber (Tooth Surface: Nylon Tooth Cloth)	Glass Fiber

Features and Cautions P.1137

Selection Method P.1967

Belt Circumference Length is the length of Core Wire.

Type	Pitch	ℓ	H	h	PLD	r	Unit Mass g/m (Width: 10mm)
P2M	2	1.30	1.3	0.73	0.254	0.2	14.0
P3M	3	1.95	2.1	1.09	0.381	0.3	22.0
P5M	5	3.25	3.6	1.81	0.571	0.5	41.0
P8M	8	5.20	5.5	2.90	0.686	0.8	56.0

Ordering Example

Part Number: PTBN 200 P2M-060

Type: PTBN Belt Number: 200 Belt Nominal Width: 060

Days to Ship Configure Online

Price Configure Online

P2M Type (Pitch:2mm)

Type	Belt Number	Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price	
					Nominal Width	060
PTBN	80 P2M	060 (6mm)	40	80		
	84 P2M		42	84		
	88 P2M		44	88		
	98 P2M		49	98		
	100 P2M		50	100		
	112 P2M		56	112		
	116 P2M		58	116		
	118 P2M		59	118		
	124 P2M		62	124		
	126 P2M		63	126		
	132 P2M		66	132		
	134 P2M		67	134		
	136 P2M		68	136		
	140 P2M		70	140		
	142 P2M		71	142		
	144 P2M		72	144		
	146 P2M		73	146		
	152 P2M		76	152		
	154 P2M		77	154		
	160 P2M		80	160		
	162 P2M		81	162		
	166 P2M		83	166		
	170 P2M		85	170		
172 P2M	86	172				
176 P2M	88	176				
180 P2M	90	180				
186 P2M	93	186				
190 P2M	95	190				
196 P2M	98	196				
200 P2M	100	200				
204 P2M	102	204				
208 P2M	104	208				
212 P2M	106	212				
214 P2M	107	214				
216 P2M	108	216				
220 P2M	110	220				
224 P2M	112	224				
230 P2M	115	230				

Type	Belt Number	Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price	
					Nominal Width	060
PTBN	234 P2M	060 (6mm)	117	234		
	236 P2M		118	236		
	240 P2M		120	240		
	244 P2M		122	244		
	246 P2M		123	246		
	250 P2M		125	250		
	258 P2M		129	258		
	262 P2M		131	262		
	266 P2M		133	266		
	270 P2M		135	270		
	274 P2M		137	274		
	280 P2M		140	280		
	284 P2M		142	284		
	290 P2M		145	290		
	300 P2M		150	300		
	302 P2M		151	302		
	310 P2M		155	310		
	318 P2M		159	318		
	320 P2M		160	320		
	324 P2M		162	324		
	328 P2M		164	328		
	330 P2M		165	330		
	334 P2M		167	334		
340 P2M	170	340				
348 P2M	174	348				
354 P2M	177	354				
360 P2M	180	360				
370 P2M	185	370				
378 P2M	189	378				
380 P2M	190	380				
390 P2M	195	390				
400 P2M	200	400				
408 P2M	204	408				
416 P2M	208	416				
420 P2M	210	420				
424 P2M	212	424				
426 P2M	213	426				
434 P2M	217	434				

Type	Belt Number	Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price	
					Nominal Width	060
PTBN	440 P2M	060 (6mm)	220	440		
	448 P2M		224	448		
	464 P2M		232	464		
	488 P2M		244	488		
	490 P2M		245	490		
	500 P2M		250	500		
	516 P2M		258	516		
	520 P2M		260	520		
	530 P2M		265	530		
	560 P2M		280	560		
	576 P2M		288	576		
	590 P2M		295	590		
	600 P2M		300	600		
	630 P2M		315	630		
	638 P2M		319	638		
	656 P2M		328	656		
	676 P2M		338	676		
	680 P2M		340	680		
	704 P2M		352	704		
	710 P2M		355	710		
	754 P2M		377	754		
	764 P2M		382	764		
	774 P2M		387	774		
788 P2M	394	788				
800 P2M	400	800				
808 P2M	404	808				
824 P2M	412	824				
846 P2M	423	846				
866 P2M	433	866				
898 P2M	449	898				
900 P2M	450	900				
940 P2M	470	940				
956 P2M	478	956				
992 P2M	496	992				
1040 P2M	520	1040				
1242 P2M	641	1242				

P3M Type (Pitch:3mm)

Type	Belt Number	Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price	
					Nominal Width	150
PTBN	120 P3M	100 (10mm)	40	120		
	123 P3M		41	123		
	138 P3M		46	138		
	141 P3M		47	141		
	144 P3M		48	144		
	147 P3M		49	147		
	150 P3M		50	150		
	153 P3M		51	153		
	159 P3M		53	159		
	162 P3M		54	162		
	171 P3M		57	171		
	174 P3M		58	174		
	177 P3M		59	177		
	183 P3M		61	183		
	186 P3M		62	186		
	192 P3M		64	192		
	195 P3M		65	195		
	198 P3M		66	198		
	201 P3M		67	201		
	207 P3M		69	207		
	210 P3M		70	210		
	213 P3M		71	213		
	219 P3M		73	219		
222 P3M	74	222				
225 P3M	75	225				
231 P3M	77	231				
234 P3M	78	234				
237 P3M	79	237				
240 P3M	80	240				
243 P3M	81	243				
246 P3M	82	246				
252 P3M	84	252				
255 P3M	85	255				
264 P3M	88	264				
270 P3M	90	270				
273 P3M	91	273				

Type	Belt Number	Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price	
					Nominal Width	150
PTBN	276 P3M	100 (10mm)	92	276		
	279 P3M		93	279		
	285 P3M		95	285		
	288 P3M		96	288		
	291 P3M		97	291		
	294 P3M		98	294		
	300 P3M		100	300		
	303 P3M		101	303		
	306 P3M		102	306		
	309 P3M		103	309		
	312 P3M		104	312		
	318 P3M		106	318		
	330 P3M		110	330		
	339 P3M		113	339		
	345 P3M		115	345		
	354 P3M		118	354		
	360 P3M		120	360		
	363 P3M		121	363		
	369 P3M		123	369		
	372 P3M		124	372		
	384 P3M		128	384		
	387 P3M		129	387		
	393 P3M		131	393		
399 P3M	133	399				
402 P3M	134	402				
411 P3M	137	411				
420 P3M	140	420				
423 P3M	141	423				
432 P3M	144	432				
447 P3M	149	447				
450 P3M	150	450				
453 P3M	151	453				
459 P3M	153	459				
477 P3M	159	477				
483 P3M	161	483				
486 P3M	162	486				

Type	Belt Number	Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price	
					Nominal Width	150
PTBN	489 P3M	100 (10mm)	163	489		
	501 P3M		167	501		
	504 P3M		168	504		
	507 P3M		169	507		
	510 P3M		170	510		
	525 P3M		175	525		
	537 P3M		179	537		
	552 P3M		184	552		
	561 P3M		187	561		
	588 P3M		196	588		
	600 P3M		200	600		
	633 P3M		211	633		
	660 P3M		220	660		
	675 P3M		225	675		
	681 P3M		227	681		
	693 P3M		231	693		
	699 P3M		233	699		
	738 P3M		246	738		
	753 P3M		251	753		
	756 P3M		252	756		
	789 P3M		263	789		
	804 P3M		268	804		
	852 P3M		284	852		
861 P3M	287	861				
879 P3M	293	879				
891 P3M	297	891				
918 P3M	306	918				
933 P3M	311	933				
948 P3M	316	948				
957 P3M	319	957				
1005 P3M	335	1005				
1023 P3M	341	1023				
1041 P3M	347	1041				
1050 P3M	350	1050				
1191 P3M	397	1191				

P5M Type (Pitch:5mm)

Type	Belt Number	Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price	
					Nominal Width	150
PTBN	215 P5M	100 (10mm)	43	215		
	225 P5M		45	225		
	255 P5M		51	255		
	260 P5M		52	260		
	275 P5M		55	275		
	295 P5M		59	295		
	300 P5M		60	300		
	310 P5M		62	310		
	320 P5M		64	320		
	325 P5M		65	325		
	340 P5M		68	340		
	350 P5M		70	350		
	370 P5M		74	370		
	375 P5M		75	375		
	400 P5M		80	400		
	420 P5M		84	420		
	425 P5M		85	425		
	430 P5M		86	430		
	440 P5M		88	440		
	450 P5M		90	450		
	475 P5M		95	475		