

Pipe Supports

Vertical Pipe Bands, Paddle Shaped Legs, T-Shaped Brackets

Vertical Pipe Bands RoHS10

| Type | Material | | Surface Treatment |
|------|---------------------|----------------------|--------------------|
| | Main Body | Protection Material | |
| KBND | Low Carbon Steel | Flexible PVC (White) | Trivalent Chromate |
| KBNS | 304 Stainless Steel | - | - |

Standard

With Protection Material Type

*t of KBND means thickness of sheet metal. Thickness of protection material is (1.5).

| Part Number | Applicable Pipe O.D. D | (L) | t | | | W | C | P | KBND | | KBNS | | KBND | |
|--------------------------|------------------------|------|------------|----------------------|------------|----|----|----|----------------------|------------|----------------------|------------|----------------------|--|
| | | | Unit Price | Volume Discount Rate | Unit Price | | | | Volume Discount Rate | Unit Price | Volume Discount Rate | Unit Price | Volume Discount Rate | |
| Standard | 10A | 17.3 | 73 | - | - | - | - | - | - | - | - | - | - | |
| KBND | 15A | 21.7 | 77 | - | - | - | - | - | - | - | - | - | - | |
| | 20A | 27.2 | 84 | - | - | - | - | - | - | - | - | - | - | |
| | 25A | 34 | 88 | 0.6 | - | 25 | 45 | 20 | - | - | - | - | - | |
| | 32A | 42.7 | 98 | 0.8 | - | - | - | - | - | - | - | - | - | |
| With Protection Material | 40A | 48.6 | 104 | - | - | - | - | - | - | - | - | - | - | |
| KBND | 50A | 60.5 | 116 | - | - | - | - | - | - | - | - | - | - | |

Be sure to use KBND in ambient temperature up to 60°C for the properties of flexible PVC.

Paddle Shaped Legs RoHS10

| Type | Material | Surface Treatment |
|------|---------------------|--------------------|
| HGA | 1018 Carbon Steel | Trivalent Chromate |
| HGAS | 304 Stainless Steel | - |

| Part Number | Type | No. | L | HGA | | HGAS | |
|-------------|------|-----|-----|------------|----------------------|------------|----------------------|
| | | | | Unit Price | Volume Discount Rate | Unit Price | Volume Discount Rate |
| HGA | HGAS | 1 | 50 | - | - | - | - |
| | | 2 | 75 | - | - | - | - |
| | | 3 | 100 | - | - | - | - |



T-Shaped Bracket RoHS10

| Type | Material | Surface Treatment |
|------|---------------------|--------------------|
| TGA | Low Carbon Steel | Trivalent Chromate |
| TGAS | 304 Stainless Steel | - |

| Part Number | Type | No. | L | (Ø) | TGA | | TGAS | |
|-------------|------|-----|-----|-----|------------|----------------------|------------|----------------------|
| | | | | | Unit Price | Volume Discount Rate | Unit Price | Volume Discount Rate |
| TGA | TGAS | 1S | 50 | 26 | - | - | - | - |
| | | 1 | 60 | 36 | - | - | - | - |
| | | 2 | 80 | 56 | - | - | - | - |
| | | 3 | 100 | 76 | - | - | - | - |

Ordering Example Part Number **KBND25A TGA2**

Days to Ship Configure Online

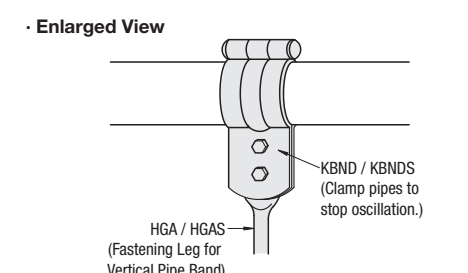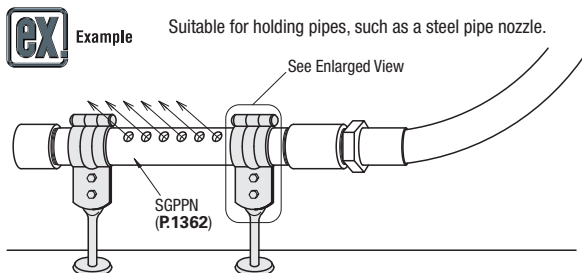

Pipe Supports

Pipe Clamps, U-Bolts for Plumbing

Pipe Straps RoHS10

| Type | Material | | Surface Treatment |
|--------|---------------------|--------------------|-------------------|
| | Double-Sided | Single-Sided | |
| RSDLN | Low Carbon Steel | Trivalent Chromate | |
| RSDLNS | 304 Stainless Steel | - | |

Double-Sided Type

Single-Sided Type

As this product is made of thin sheet metal, (L) and (P) dimensions are just for reference. KSDLN32A, 40A, and 50A have no rib. Diameter of mounting hole is Ø5, and distance from the end is (10).

Double-Sided Type

| Part Number | Type | No. | Applicable Pipe O.D. D | (L) | | (P) | | W | RSDLN | | RSDLNS | |
|-------------|--------|-----|------------------------|-------|--------|-------|--------|----|------------|----------------------|------------|----------------------|
| | | | | RSDLN | RSDLNS | RSDLN | RSDLNS | | Unit Price | Volume Discount Rate | Unit Price | Volume Discount Rate |
| RSDLN | RSDLNS | 15A | 21.7 | 60 | 60 | 47 | 47 | 19 | - | - | - | - |
| | | 20A | 27.2 | 65 | 65 | 52 | 52 | - | - | - | - | |
| | | 25A | 34.0 | 73 | 72 | 60 | 59 | - | - | - | - | |
| | | 32A | 42.7 | 81 | 86 | 68 | 73 | - | - | - | - | |
| | | 40A | 48.6 | 86 | 88 | 73 | 75 | - | - | - | - | |
| | | 50A | 60.5 | 100 | 102 | 87 | 89 | - | - | - | - | |

Single-Sided Type

| Part Number | Type | No. | Applicable Pipe O.D. D | (L) | | t | | W | | KSDLN | | KSDLS | |
|-------------|-------|-----|------------------------|-------|-------|-------|-------|-------|-------|------------|----------------------|------------|----------------------|
| | | | | KSDLN | KSDLS | KSDLN | KSDLS | KSDLN | KSDLS | Unit Price | Volume Discount Rate | Unit Price | Volume Discount Rate |
| KSDLN | KSDLS | 15A | 21.7 | 45 | 49 | 1.6 | 1.2 | 25 | 20 | - | - | - | - |
| | | 20A | 27.2 | 50 | 54.5 | | | | | - | - | - | - |
| | | 25A | 34 | 57 | 67 | | | | | - | - | - | - |
| | | 32A | 42.7 | 71 | 75 | 2 | 25 | 25 | - | - | - | - | |
| | | 40A | 48.6 | 77 | 82 | | | | - | - | - | - | |
| | | 50A | 60.5 | 89 | 99 | | | | - | - | - | - | |

U-Bolts for Plumbing

UB (Main Body) **UBSU** (Included Nut)

Material: (Low Particle Generation Type) / (302HQ Stainless Steel (304 Stainless Steel))

Surface Treatment: Reference Mass (g/m) / Accessories: Nut 2 pcs. (SWRCH Carbon Steel Trivalent Chromate)

| Part Number | Type | No. | Applicable Pipe Dia. of Pipes | *Pipe O.D. (mm) | M (Coarse) | (H) | L | UB | | UBSU | | Nut Size | | | |
|-------------|------|-------|-------------------------------|-----------------|------------|------|------|------------|----------------------|------------|----------------------|------------|----|------|-----|
| | | | | | | | | Unit Price | Volume Discount Rate | Unit Price | Volume Discount Rate | M (Coarse) | B | C | T |
| UB | UBSU | 3 | 10A | 17.3 | M4 | 34 | 21.3 | - | - | - | - | M4 | 7 | 8.1 | 3.2 |
| | | 4 | 15A | 21.7 | M4 | 37 | 25.7 | - | - | - | - | M5 | 8 | 9.2 | 4 |
| | | 4-M5 | | | M5 | 26.7 | - | - | - | - | | | | | |
| | | 6 | 20A | 27.2 | M4 | 39 | 31.2 | - | - | - | - | M6 | 10 | 11.5 | 5 |
| | | 6-M5 | | | M5 | 32.2 | - | - | - | - | | | | | |
| | | 8 | 25A | 34.0 | M4 | 43 | 38 | - | - | - | - | - | - | - | - |
| | | 8-M5 | | | M5 | 39 | - | - | - | - | | | | | |
| | | 10 | 32A | 42.7 | M5 | 47 | 47.7 | - | - | - | - | - | - | - | - |
| | | 10-M6 | | | M6 | 48.7 | - | - | - | - | | | | | |
| | | 12 | 40A | 48.6 | M5 | 50 | 53.6 | - | - | - | - | - | - | - | - |
| | | 16 | | | M5 | 57 | 65.5 | - | - | - | - | | | | |

*O.D. (mm) of pipes is for reference only.

Ordering Example Part Number **RSDLN15A UB4 UBSU10-M6**

Days to Ship Configure Online