


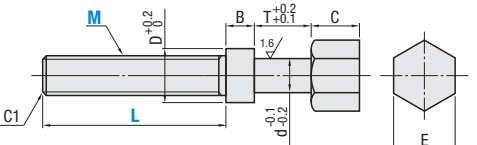
Adjusting Bolts

T Dimension Compact



RoHS 10

Threads	Type	Material	Surface Treatment
Coarse Thread	AJST	1045 Carbon Steel or Equivalent	Black Oxide
	AJSTM	1045 Carbon Steel or Equivalent	Electroless Nickel Plating
	AJSTS	304 Stainless Steel	—
Fine Thread	AJSTF	1045 Carbon Steel or Equivalent	Black Oxide
	AJSTMF	1045 Carbon Steel or Equivalent	Electroless Nickel Plating
	AJSTFS	304 Stainless Steel	—




25/(1.6/)

Part Number	Type	M	L 5 mm Increment	d	T	M x Pitch		B	D	C	E	Available Types					
						Fine	Coarse					Coarse Thread			Fine Thread		
												AJST	AJSTM	AJSTS	AJSTF	AJSTMF	AJSTFS
Coarse		3	10-45	2.5	7	—	3 x 0.5	3	4.5	5	6	•	•	•	—	—	—
AJST		4	10-60	3.5	7	4 x 0.5	4 x 0.7	3	5.5	7	7	•	•	•	•	•	•
AJSTM		5	10-70	4.5	9	5 x 0.5	5 x 0.8	4.6	7.5	10	8	•	•	•	•	•	•
AJSTS		6	15-80	5.5	9	6 x 0.75	6 x 1.0	4.6	8.5	10	10	•	•	•	•	•	•
Fine		8	20-100	7.5	12	8 x 0.75	8 x 1.25	6	11.5	15	13	•	•	•	•	•	•
AJSTF		10	25-100	9.5	16	10 x 1.0	10 x 1.5	7	15.5	20	17	•	•	•	•	•	•
AJSTMF		12	25-150	11.5	19	12 x 1.0	12 x 1.75	7	17.5	20	19	•	•	•	•	•	•
AJSTFS		16	25-150	15.5	19	—	16 x 2.0	8	21.5	20	24	•	•	•	•	•	•


Applicable block for Adjusting Bolts to T Dimension Compact Type is Side Mounting T Dimension Compact Type P1712

Part Number Example: **AJST8 - 25**



RoHS 10

Threads	Type	Material	Surface Treatment
Coarse Thread	AJSTC	1045 Carbon Steel or Equivalent	Black Oxide
	AJSTCM	1045 Carbon Steel or Equivalent	Electroless Nickel Plating
	AJSTCS	304 Stainless Steel	—
Fine Thread	AJSTCF	1045 Carbon Steel or Equivalent	Black Oxide
	AJSTCMF	1045 Carbon Steel or Equivalent	Electroless Nickel Plating
	AJSTCFS	304 Stainless Steel	—

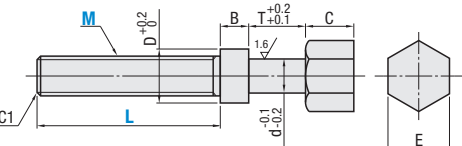

25/(1.6/)

Part Number	Type	M	L 5 mm Increment	d	T	M x Pitch		B	D	C	E
						Fine	Coarse				
Coarse		4	10-60	3.5	3	4 x 0.5	4 x 0.7	3	5.5	5	7
AJSTC		5	10-70	4.5	5	5 x 0.5	5 x 0.8	4.6	7.5	8	8
AJSTCM		6	15-80	5.5	5	6 x 0.75	6 x 1.0	4.6	8.5	10	10
AJSTCS		8	20-100	7.5	5	8 x 0.75	8 x 1.25	6	11.5	15	13
Fine		8	20-100	7.5	5	8 x 0.75	8 x 1.25	6	11.5	15	13
AJSTCF		8	20-100	7.5	5	8 x 0.75	8 x 1.25	6	11.5	15	13
AJSTCMF		8	20-100	7.5	5	8 x 0.75	8 x 1.25	6	11.5	15	13
AJSTCFS		8	20-100	7.5	5	8 x 0.75	8 x 1.25	6	11.5	15	13

 
Applicable block for Adjusting Bolts to T Dimension Compact Type is Side Mounting T Dimension Compact Type P1712

Part Number Example: **AJSTC8 - 25**

Application Example: Adjusting Bolt (AJSTC) with Block for Adjusting Bolts (AJSCC - P.1712)


Adjusting Bolts

Hex Socket Head / Hex Socket Knurled Knobs / Knurled Knobs Type



RoHS 10

Thread	Type	Material	Surface Treatment
Coarse Thread	AJSTR	1045 Carbon Steel or Equivalent	Black Oxide
	AJSTMTR	1045 Carbon Steel or Equivalent	Electroless Nickel Plating
	AJSTRS	304 Stainless Steel	—

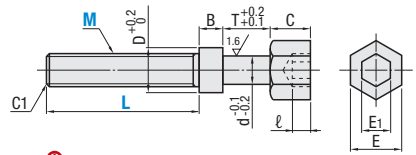


25/(1.6/)

The outer hex head E and the hex socket E₁ are not the same.


Part Number	Type	M	L 5 mm Increment	d	T	M x Pitch		B	D	C	E	E ₁	ℓ
						Coarse Thread	Fine Thread						
AJSTR		4	10-50	3.5	7	4 x 0.7	3	5.5	5	7	2.5	2.5	
AJSTMTR		5	10-50	4.5	9	5 x 0.8	4.6	7.5	10	8	3	3	
AJSTRS		6	15-50	5.5	9	6 x 1.0	4.6	8.5	10	10	4	4	
AJSTRS		8	20-50	7.5	12	8 x 1.25	6	11.5	15	13	5	5	

Part Number Example: **AJSTR4 - 20**



RoHS 10

Thread	Type	Material	Surface Treatment
Coarse Thread	AJKTN	1045 Carbon Steel or Equivalent	Black Oxide
	AJKTNM	1045 Carbon Steel or Equivalent	Electroless Nickel Plating
	AJKTNS	304 Stainless Steel	—
Fine Thread	AJKTNF	1045 Carbon Steel or Equivalent	Black Oxide
	AJKTNMF	1045 Carbon Steel or Equivalent	Electroless Nickel Plating

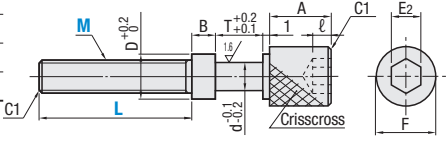


25/(1.6/)

Crisscross


Part Number	Type	M	L 5 mm Increment	d	T	M x Pitch		B	D	A	F	E ₂	ℓ	Available Types				
						Fine Thread	Coarse Thread							AJKTN	AJKTNM	AJKTNS	AJKTNF	AJKTNMF
Coarse		3	10-45	2.5	7	—	3 x 0.5	3	4.5	7	10	5	4	•	•	—	—	—
AJKTN		4	10-60	3.5	7	4 x 0.5	4 x 0.7	3	5.5	7	10	5	4	•	•	—	—	—
AJKTNM		5	10-70	4.5	9	5 x 0.5	5 x 0.8	4.6	7.5	15	15	8	7	•	•	•	•	•
AJKTNS		6	15-80	5.5	9	6 x 0.75	6 x 1.0	4.6	8.5	15	15	8	7	•	•	•	•	•
Fine		8	20-100	7.5	12	8 x 0.75	8 x 1.25	6	11.5	25	20	10	9	•	•	•	•	•
AJKTNF		10	25-100	9.5	16	10 x 1.0	10 x 1.5	7	15.5	25	20	10	9	•	•	•	•	•
AJKTNMF		12	25-150	11.5	19	12 x 1.0	12 x 1.75	7	17.5	25	20	10	9	•	•	•	•	•
AJKTNMF		16	25-150	15.5	19	—	16 x 2.0	8	21.5	24	20	10	9	•	•	•	•	•

Part Number Example: **AJKTN10 - 80**



RoHS 10

Thread	Type	Material	Surface Treatment
Coarse Thread	AJSTK	1045 Carbon Steel or Equivalent	Black Oxide
	AJSTKM	1045 Carbon Steel or Equivalent	Electroless Nickel Plating
	AJSTKS	304 Stainless Steel	—

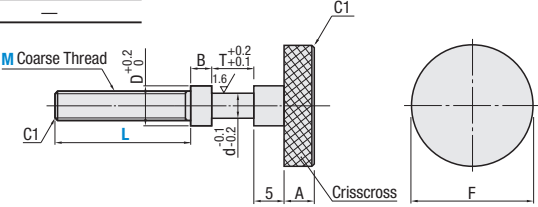

25/(1.6/)

Crisscross

Part Number	Type	M (Coarse)	L 5 mm Increment	d	T	B	D	A	F
AJSTKM		4	10-30	3.5	7	3	5.5	4	16
AJSTKS		5	10-40	4.5	9	4.6	7.5	6	20
AJSTKS		6	15-50	5.5	9	4.6	8.5	6	20
AJSTKS		8	20-50	7.5	12	6	11.5	6	20

Part Number Example: **AJSTK4 - 25**