



Manifold Blocks (Hydraulic / Pneumatic)

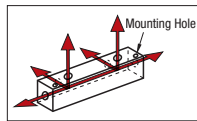

Manifold Blocks – Hydraulic


BMUN

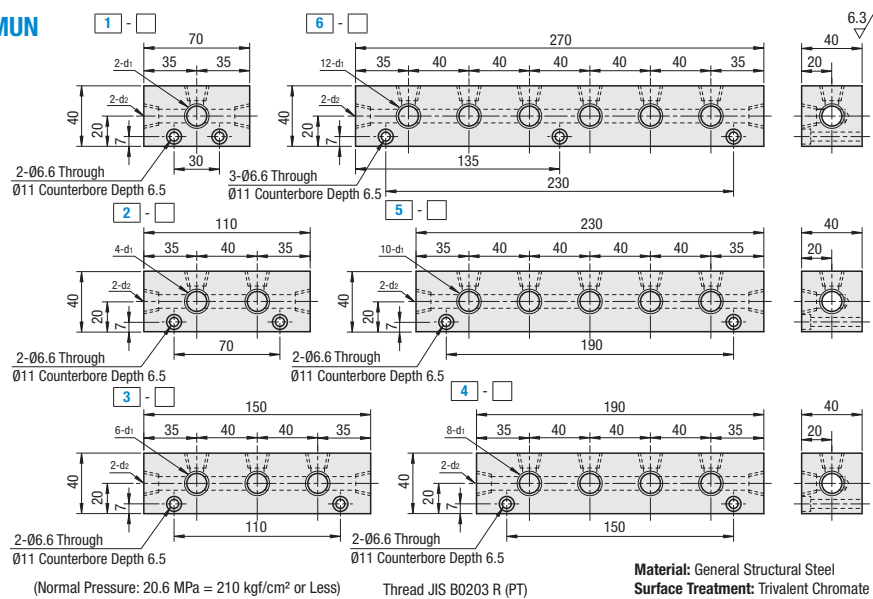

RoHS 10

Manifold Blocks – Pneumatic

BMUAN

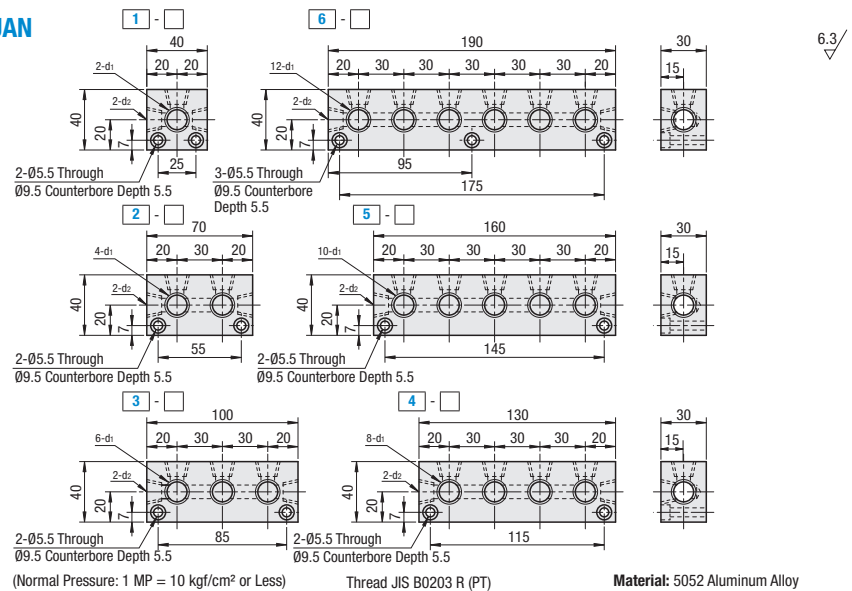


RoHS 10

Type	Part Number		d ₁ Rc (PT)	d ₂ Rc (PT)
	No.			
BMUN Hydraulic	1	33	3/8	3/8
		13	1/8	3/8
	2	22	1/4	1/4
		23	1/4	3/8
		34	3/8	1/2
	3	22	1/4	1/4
		23	1/4	3/8
		33	3/8	3/8
	4	12	1/8	1/4
		22	1/4	1/4
		23	1/4	3/8
	5	23	1/4	3/8
		34	3/8	1/2

Type	Part Number		d ₁ Rc (PT)	d ₂ Rc (PT)
	No.			
BMUAN Pneumatic	1	22	1/4	1/4
		11	1/8	1/8
	2	12	1/8	1/4
		22	1/4	1/4
		11	1/8	1/8
	3	12	1/8	1/4
		22	1/4	1/4
		12	1/8	1/4
	4	12	1/8	1/4
		22	1/4	1/4
		12	1/8	1/4
	5	22	1/4	1/4
		12	1/8	1/4
	6	12	1/8	1/4
		22	1/4	1/4


Part Number Example: BMUN2-22, BMUAN4-22

 Manifold Blocks (Pneumatic)



Manifold Blocks – Pneumatic


BMIAN

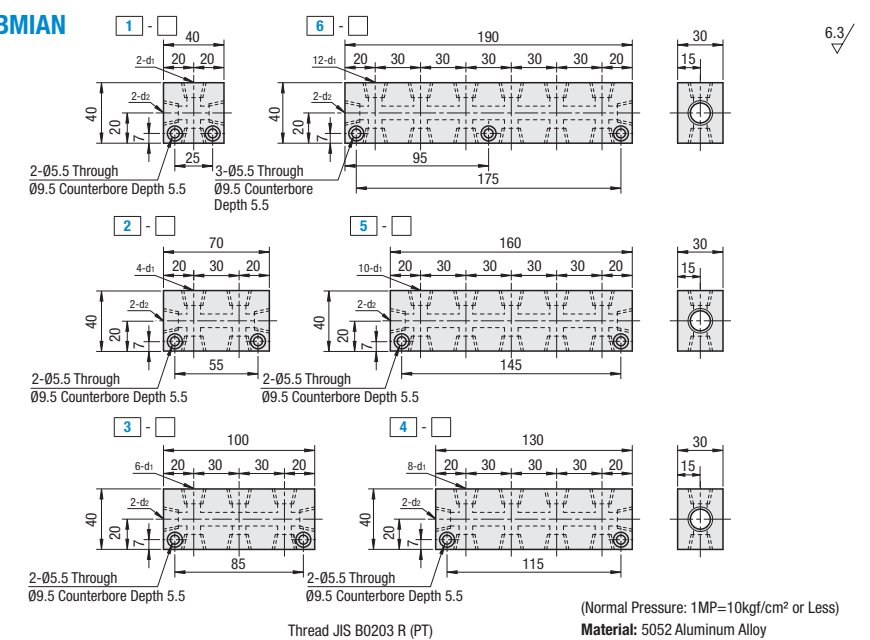

RoHS 10

Manifold Blocks – Pneumatic

BMSLN

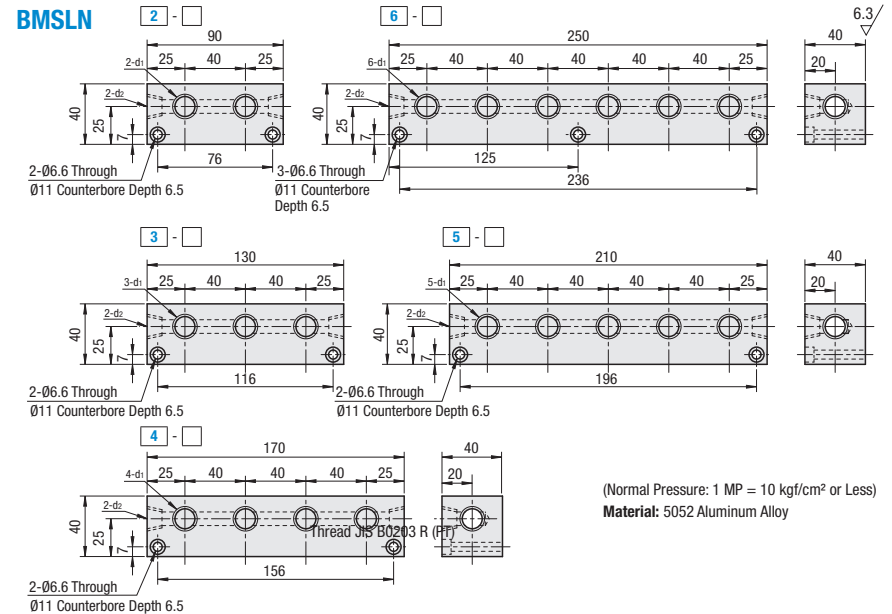

RoHS 10

Type	Part Number		d ₁ Rc (PT)	d ₂ Rc (PT)
	No.			
BMIAN Hydraulic	1	11	1/8	1/8
		22	1/4	1/4
	2	11	1/8	1/8
		12	1/8	1/4
		22	1/4	1/4
	3	11	1/8	1/8
		22	1/4	1/4
		11	1/8	1/8
	4	12	1/8	1/4
		22	1/4	1/4
		12	1/8	1/4
	5	12	1/8	1/4
		22	1/4	1/4
	6	11	1/8	1/8
		22	1/4	1/4

Type	Part Number		d ₁ Rc (PT)	d ₂ Rc (PT)
	No.			
BMSLN Pneumatic	2	24	1/4	1/2
		33	3/8	3/8
	3	44	1/2	1/2
		33	3/8	3/8
		44	1/2	1/2
	4	23	1/4	3/8
		24	1/4	1/2
		33	3/8	3/8
	5	44	1/2	1/2
		24	1/4	1/2
		33	3/8	3/8
	6	44	1/2	1/2
		23	1/4	3/8

Part Number Example: BMIAN3-22